


General-Purpose, Thermometers Economical, Ideal for School and Laboratory Applications!

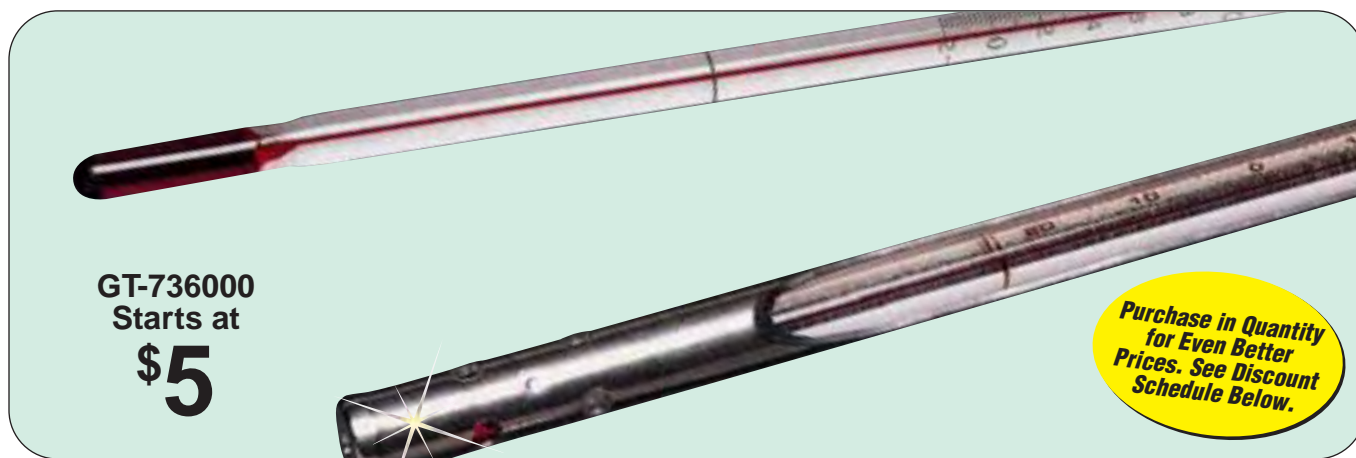

GT-736000
Starts at
\$5

**Purchase in Quantity
for Even Better
Prices. See Discount
Schedule Below.**

Photos are representative. Lower thermometer shown with optional armor case, GTA-611255, \$40 additional.

- ✓ Red Liquid-Filled Models
- ✓ Partial and Total Immersion Styles
- ✓ 305 mm (12") and 150 mm (6") Lengths
- ✓ Variety of Single and Dual Temperature Ranges

**Perfect Where
Glass Thermometers
are Purchased
Frequently!**

Economical glass-bulb thermometers are ideal for school and laboratory applications. These general-purpose, easy-to-read white back units are available with red liquid filling, in a variety of ranges and styles.



Available with red safety liquid, in a variety of ranges and styles.

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)				
Model No.	Range	Length mm (in)	Div	Price
Red Organic Safety, White Back, Partial Immersion Calibrated at 76 mm				
GT-736570	-20 to 110°C	305 (12)	1°	\$6.00
GT-736580	-20 to 150°C	305 (12)	1°	7.00
GT-737000	0 to 230°F	305 (12)	1°	6.00
GT-736780	-20 to 110°C/ 0 to 230°F	305 (12)	1°C/ 2°F	8.00
Red Organic Safety, White Back, Total Immersion				
GT-736590	-20 to 110°C	305 (12)	1°	\$6.50
GT-736600	-20 to 150°C	305 (12)	1°	7.00
GT-737680	-20 to 110°C/ 0 to 230°F	305 (12)	1°C/ 2°F	8.00
Low Range Red Organic Safety, White Back, Total Immersion				
GT-736620	-50 to 50°C	305 (12)	1°	\$7.00
Student Red Organic Safety, Partial Immersion Calibrated at 76 mm				
GT-736630	-10 to 110°C	150 (6)	1°	\$5.00
GT-738640	-10 to 110°C/ 0 to 230°F	150 (6)	1°C/ 2°F	6.00

Comes in a protective plastic shipping tube.

Ordering Examples: GT-737680, dual range (-20 to 110°C/ 0 to 230°F) total immersion, red safety thermometer, **\$8.**

Discount Schedule for Economical Thermometers

11 to 24 Units10%
25 to 49 Units15%
50 to 9920%

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters