

Transition Junction Style Probes


with High Temperature Moulded Construction

- Made from Class1 (Special Limits of Error) Material
- 150 mm and 300 mm Lengths in Stock†
- Sheath Diameters from 0.25 mm to 3mm
- 304, 310, 316, 321SS, Inconel or Super OMEGACLAD™XL Sheath
- Grounded, Ungrounded or Exposed Junction
- 1m Teflon®-Coated Lead Wires Standard
- Environmentally Friendly Cadmium-Free Liquid Crystal Polymer Moulded Transition Junction Rated to 260°C



Models Highlighted have SUPEROMEGACLAD™ XL Sheaths! See Page A-84 for Details

Discount Schedule	
1-10 Units.....	Net
11-24 Units.....	10%
25-49 Units.....	20%
50 and Up.....	Consult Sales

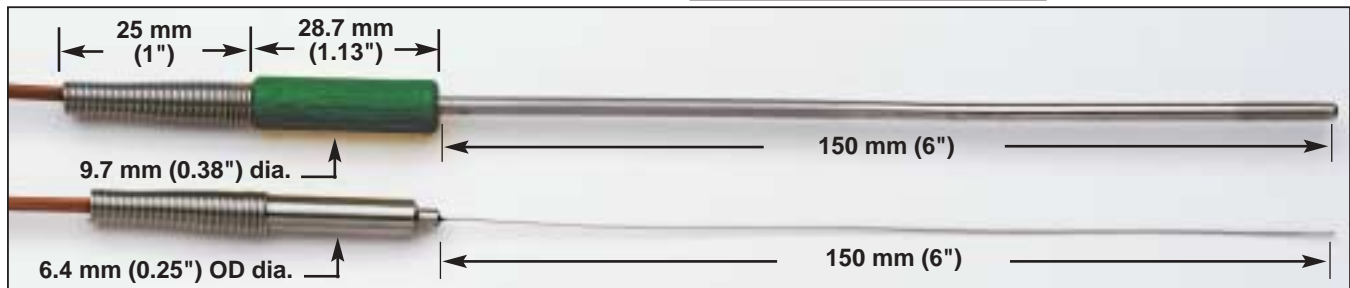

Note: Probes with 1mm diameter and larger supplied with moulded transition joints. Smaller-size probes supplied with stainless steel transition joints. All type-N probes supplied with stainless steel transition joints.

To Order (Specify Model Number)			ALL MODELS IN STOCK FOR FAST DELIVERY!					
Thermocouple Alloy	Sheath Dia.	Model No. 150mm Length	Price		Model No. 300mm Length	Price		Price Per Add'l. 150mm
			G*/E*	U*		G*/E*	U*	
Iron-Constantan 304 SS Sheath J	0.25	HJMTSS-M025(*)-150	£42.00	£58.00	HJMTSS-M025(*)-300	£43.00	£59.00	£1.05
	0.50	HJMTSS-M050(*)-150	25.50	27.00	HJMTSS-M050(*)-300	26.00	27.50	0.55
	0.75	HJMTSS-M075(*)-150	25.50	27.00	HJMTSS-M075(*)-300	26.00	27.50	0.55
	1.00	HJMTSS-M100(*)-150	25.50	27.00	HJMTSS-M100(*)-300	26.00	27.50	0.55
	1.50	HJMTSS-M150(*)-150	22.25	23.75	HJMTSS-M150(*)-300	22.75	24.50	0.65
	3.00	HJMTSS-M300(*)-150	22.25	23.75	HJMTSS-M300(*)-300	23.00	24.50	0.80
CHROMEGA™ ALOMEGA™ 304 SS Sheath K	0.25	HKMTSS-M025(*)-150	42.00	58.00	HKMTSS-M025(*)-300	43.00	59.00	1.05
	0.50	HKMTSS-M050(*)-150	25.50	27.00	HKMTSS-M050(*)-300	26.00	27.50	0.55
	0.75	HKMTSS-M075(*)-150	25.50	27.00	HKMTSS-M1075(*)-300	26.00	27.50	0.55
	1.00	HKMTSS-M100(*)-150	25.50	27.00	HKMTSS-M100(*)-300	26.00	27.50	0.55
	1.50	HKMTSS-M150(*)-150	22.25	23.75	HKMTSS-M150(*)-300	22.75	24.50	0.65
	3.00	HKMTSS-M300(*)-150	22.25	23.75	HKMTSS-M300(*)-300	23.00	24.50	0.80
CHROMEGA™ ALOMEGA™ Super OMEGACLAD™XL Sheath K	0.50	HKMTXL-M050(*)-150	28.00	29.50	HKMTXL-M050(*)-300	28.50	30.00	0.55
	0.75	HKMTXL-M075(*)-150	28.00	29.50	HKMTXL-M075(*)-300	28.50	30.00	0.55
	1.00	HKMTXL-M100(*)-150	28.00	29.50	HKMTXL-M100(*)-300	28.50	30.00	0.55
	1.50	HKMTXL-M150(*)-150	24.50	26.00	HKMTXL-M150(*)-300	25.50	27.00	0.70
	3.00	HKMTXL-M300(*)-150	24.50	26.00	HKMTXL-M300(*)-300	25.50	27.00	1.45
	OMEGA-P™ OMEGA-N™ Super OMEGACLAD™XL Sheath N	0.50	HNMTXL-M050(*)-150	28.00	29.50	HNMTXL-M050(*)-300	28.50	30.00
0.75		HNMTXL-M075(*)-150	28.00	29.50	HNMTXL-M075(*)-300	28.50	30.00	0.55
1.00		HNMTXL-M100(*)-150	28.00	29.50	HNMTXL-M100(*)-300	28.50	30.00	0.55
1.50		HNMTXL-M150(*)-150	24.50	26.00	HNMTXL-M150(*)-300	25.50	27.00	0.70
3.00		HNMTXL-M300(*)-150	24.50	26.00	HNMTXL-M300(*)-300	25.50	27.00	1.45
CHROMEGA™ Constanant 304 SS Sheath E		0.25	HEMTSS-M025(*)-150	42.00	58.00	HEMTSS-M025(*)-300	43.00	59.00
	0.50	HEMTSS-M050(*)-150	25.50	27.00	HEMTSS-M050(*)-300	26.00	27.50	0.55
	0.75	HEMTSS-M075(*)-150	25.50	27.00	HEMTSS-M075(*)-300	26.00	27.50	0.55
	1.00	HEMTSS-M100(*)-150	25.50	27.00	HEMTSS-M100(*)-300	26.00	27.50	0.55
	1.50	HEMTSS-M150(*)-150	22.25	23.75	HEMTSS-M150(*)-300	22.75	24.50	0.65
	3.00	HEMTSS-M300(*)-150	22.25	23.75	HEMTSS-M300(*)-300	23.00	24.50	0.80
Copper-Constantan 304 SS Sheath T	0.50	HTMTSS-M050(*)-150	25.50	27.00	HTMTSS-M050(*)-300	26.00	27.50	0.55
	0.75	HTMTSS-M075(*)-150	25.50	27.00	HTMTSS-M075(*)-300	26.00	27.50	0.55
	1.00	HTMTSS-M100(*)-150	25.50	27.00	HTMTSS-M100(*)-300	26.00	27.50	0.55
	1.50	HTMTSS-M150(*)-150	22.25	23.75	HTMTSS-M150(*)-300	22.75	24.50	0.65
	3.00	HTMTSS-M300(*)-150	22.25	23.75	HTMTSS-M300(*)-300	23.00	24.50	0.80

*Specify junction type: E (exposed), G (grounded) or U (ungrounded).

†Other lengths available, consult Sales Department

To order with Inconel Sheath, Change "SS" in model no. to "IN". No additional charge. Example: HKMTIN-M300G-150, £22.25.

Ordering Example: HKMTSS-M300G-150, subminiature transition joint probe, type K, 3mm O.D. stainless steel sheath, 150mm length, grounded junction, £22.25