


Mica-Glass Insulated Ultra High Temperature Heater Hook-up Wire



HTMG Series

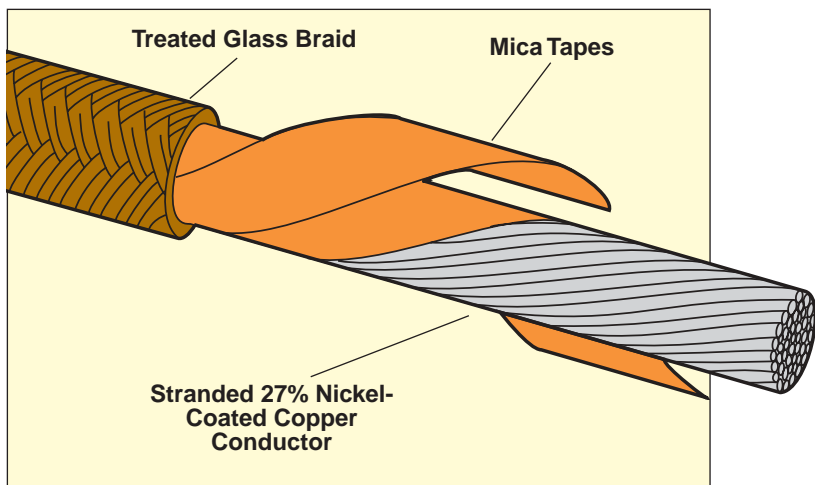

- ✓ 450°C (842°F) Temperature Rating
- ✓ CSA Certified, NRTL and UL Listed
- ✓ Single Stranded 27% Nickel Coated Copper Conductor
- ✓ Mica Tape Insulation with Treated Glass Overbraid

Discount Schedule	
15 to 29m	20%
30 to 59m	30%
60 to 149m	40%
150m and up	60%

HTMG high-temperature lead wires are designed for appliances and industrial heating products – such as commercial food service equipment, heaters, heat treating furnaces, kilns, heater elements and other applications up to 450°C (842°F).

**ALL MODELS STOCKED FOR FAST DELIVERY
MOST POPULAR MODELS HIGHLIGHTED!**

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)						
Gauge	Model No.	Type Price/Metre	Stranded	Volts	NOM OD, mm (in) ±.15 (± .006)	Approx. Wt. kg/300m (lb/1000 ft)
22	HTMG-1CU-322S/C	£2.70	7 x 30	300	1.98 (.078)	2.5 (5.5)
22	HTMG-1CU-622S/C	3.90		600	2.64 (.104)	3.2 (7.0)
20	HTMG-1CU-320S/C	3.50	10 x 30	300	2.11 (.083)	3.2 (7.0)
20	HTMG-1CU-620S/C	4.30		600	2.79 (.110)	4.1 (9.0)
18	HTMG-1CU-318S/C	3.90	16 x 30	300	2.41 (.095)	4.3 (9.5)
18	HTMG-1CU-618S/C	4.90		600	2.97 (.117)	5.2 (11.5)
16	HTMG-1CU-316S/C	4.90	26 x 30	300	2.69 (.106)	5.9 (13.0)
16	HTMG-1CU-616S/C	6.00		600	3.28 (.129)	6.8 (15.0)
14	HTMG-1CU-314S/C	6.60	41 x 30	300	3.02 (.119)	8.4 (18.5)
14	HTMG-1CU-614S/C	7.70		600	3.66 (.144)	9.5 (21.0)
12	HTMG-1CU-312S/C	8.90	65 x 30	300	3.48 (.137)	12.2 (27.0)
12	HTMG-1CU-612S/C	10.25		600	4.09 (.161)	13.4 (29.5)
10	HTMG-1CU-310S/C	15.00	105 x 30	300	5.11 (.201)	21.1 (46.5)
10	HTMG-1CU-610S/C	16.75		600	5.69 (.224)	22.9 (50.5)
8	HTMG-1CU-308S/C	23.75	133 x 29	300	6.02 (.237)	31.8 (70.0)
8	HTMG-1CU-608S/C	26.00		600	6.05 (.262)	34.2 (75.5)

Standard colour: natural (tan)

Ordering Example: HTMG-1CU-618S/C, 30 metre spool of 18 gauge stranded wire, £4.90 x 30 - 30% = £102.90
See Heater Hook-up Wire Introduction for current carrying capacity and derating.

