



RTD Probes with M12 Moulded Connectors


Imperial and Metric Sizes

PR-22 Series Starts at
£24.75



PR-22-3-100-A-1/8-0600-M12, £26, shown actual size.

- ✓ -30 to 350°C Probe Temperature Range (Class A) Standard, -50 to 500°C (Class B)
- ✓ -50 to 90°C Connector Temperature Range
- ✓ 316 Stainless Steel Probe in Imperial and Metric Diameters
- ✓ Many Standard Lengths Available
- ✓ IP67 Moulded 4-Pin M12 Connector

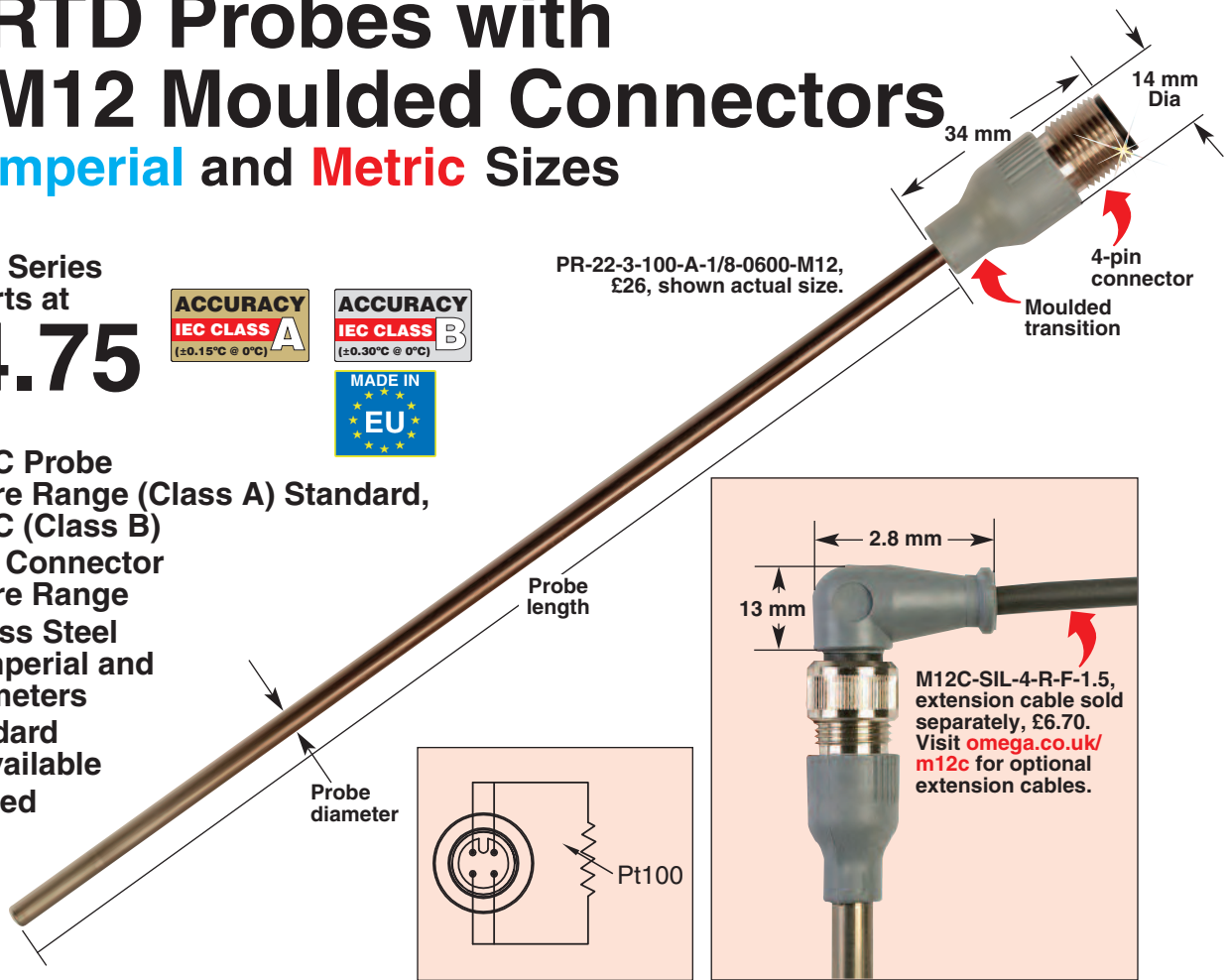

Imperial

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)				
Model Number	Price		Probe Length	Element Specification
	1/8" Dia	1/4" Dia		
PR-22-3-100-A-(*)-0600-M12	£26	£29.50	6"	Pt100, Class A
PR-22-3-100-A-(*)-0900-M12	28	31.50	9"	Pt100, Class A
PR-22-3-100-A-(*)-1200-M12	30	33.50	12"	Pt100, Class A
PR-22-3-100-A-(*)-1800-M12	34	37.50	18"	Pt100, Class A
PR-22-3-100-A-(*)-2400-M12	38	41.50	24"	Pt100, Class A

(*) = Insert probe diameter of 1/8" of 1/4 inches.

For Class B, change "-A" in model number to "-B" and subtract £2.70 from the price.

Ordering Examples: PR-22-3-100-A-1/8-0600-M12, 1/8" diameter by 6" long Pt100 Class A RTD sensor with moulded M12 connector, £26.

PR-22-3-100-A-1/4-1200-M12, 1/4" diameter by 12" long Pt100 Class A RTD sensor with moulded M12 connector, £33.50

Metric

Model Number	Price			Probe Length	Element Specification
	2 mm Dia	3 mm Dia	6 mm Dia		
PR-22-3-100-A-(*)-100-M12	–	£24.75	£28	100 mm	Pt100, Class A
PR-22-3-100-A-(*)-150-M12	£41	26	29.50	150 mm	Pt100, Class A
PR-22-3-100-A-(*)-250-M12	42	28	32	250 mm	Pt100, Class A
PR-22-3-100-A-(*)-350-M12	–	30	35	350 mm	Pt100, Class A
PR-22-3-100-A-(*)-500-M12	–	35	39	500 mm	Pt100, Class A
PR-22-3-100-A-(*)-750-M12	–	42	45.50	750 mm	Pt100, Class A
PR-22-3-100-A-(*)-1000-M12	–	49	52	1000 mm	Pt100, Class A

(*) = Insert probe diameter of "M2", "M3" or "M6" for 2 mm, 3 mm or 6 mm probe diameters shown in table. (M2 only available in 150 mm and 250 mm lengths.

For Class B, change "-A" in model number to "-B" and subtract £2.70 from the price.

Ordering Examples: PR-22-3-100-A-M3-250-M12, 3 mm diameter by 250 mm long Pt100 Class A RTD sensor with moulded M12 connector, £28.

PR-22-3-100-A-M6-500-M12, 6 mm diameter by 500 mm long Pt100 Class A RTD sensor with moulded M12 connector, £39.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters