


# Precision RTD Probes for Laboratory Applications For Measuring Temperature in Gas and Air Applications

Starts at  
**\$83**



- ✓ High-Accuracy 100 Class "A" DIN Platinum Element Standard
- ✓ Includes Stainless Steel Flange and Sheath for Easy Installation

- ✓ 3-Wire Construction for Connecting to Most Instruments

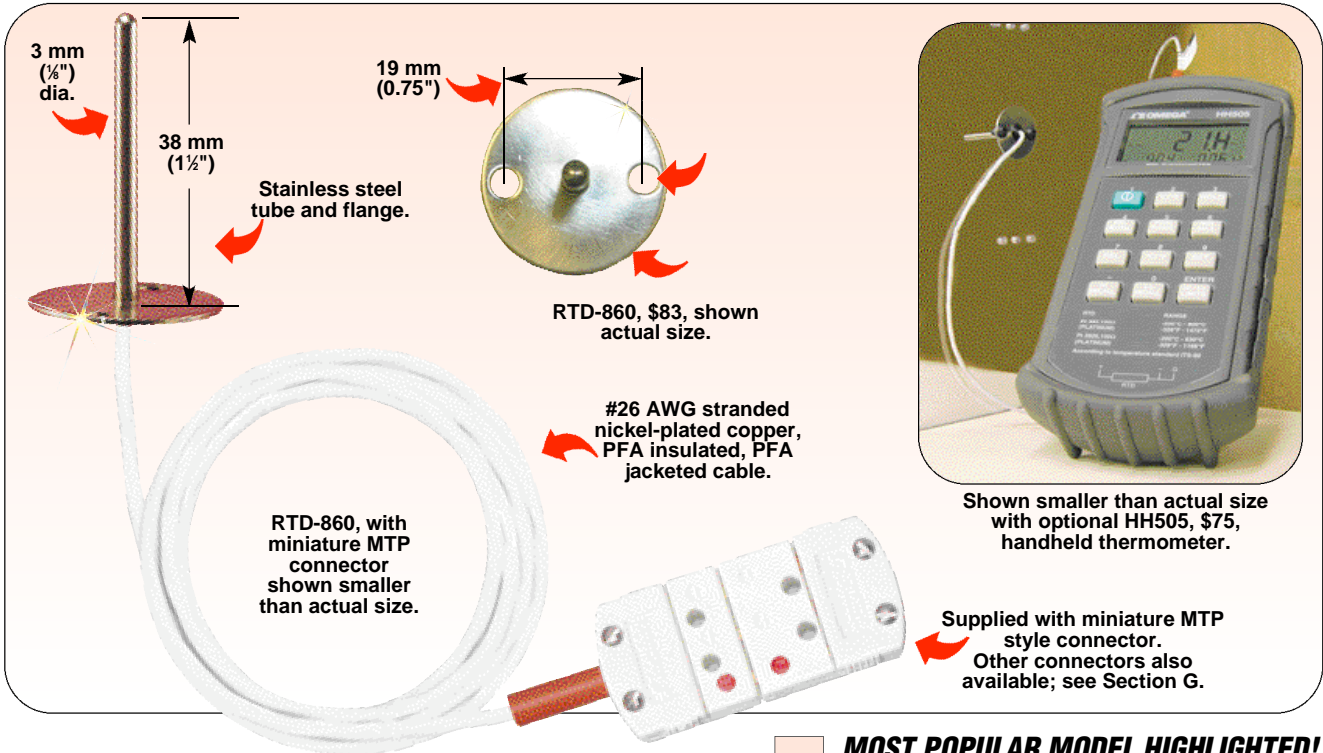

**MOST POPULAR MODEL HIGHLIGHTED!**

To Order (Specify Model Number)				
Model Number	Sensing Element	Cable	Max Temperature	Price
RTD-860	100 Class "A" DIN	1 m (40") Long PFA Insulated	230°C (450°F)	<b>\$83</b>
RTD-860-OTP	100 Class "A" DIN	1 m (40") Long PFA with OTP Conn.	230°C (450°F)	90
RTD-860-SPRTXM1	100 Class "A" DIN	1 m (40") Long PFA SPRTX-MTH	230°C (450°F)	158

**Terminations Available:** Provided with standard miniature connector; for larger sized connector add "-OTP" to model number and \$7 to price; for audio connector add "-TA3F" to model number and \$17 to price.

**Ordering Examples:** RTD-860-OTP, Class "A" accuracy with standard sized connector, \$83 + 7 = \$90. RTD-860-TA3F, Class A accuracy with audio connector, \$83 + 17 = \$100.

**Popular Options Include:**

SPRTX, 4 to 20 mA Transmitter, \$75. See page N-7.

CNI3253, Controller, \$195. See page P-19.

TX91/92, Miniature Temperature Transmitter, \$188. See page N-13.

AD128, Portable Data Logger, \$799. Visit [omega.com](http://omega.com).

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters