


# High Temperature Jack Panels

## For SHX **Miniature** Ceramic Connectors

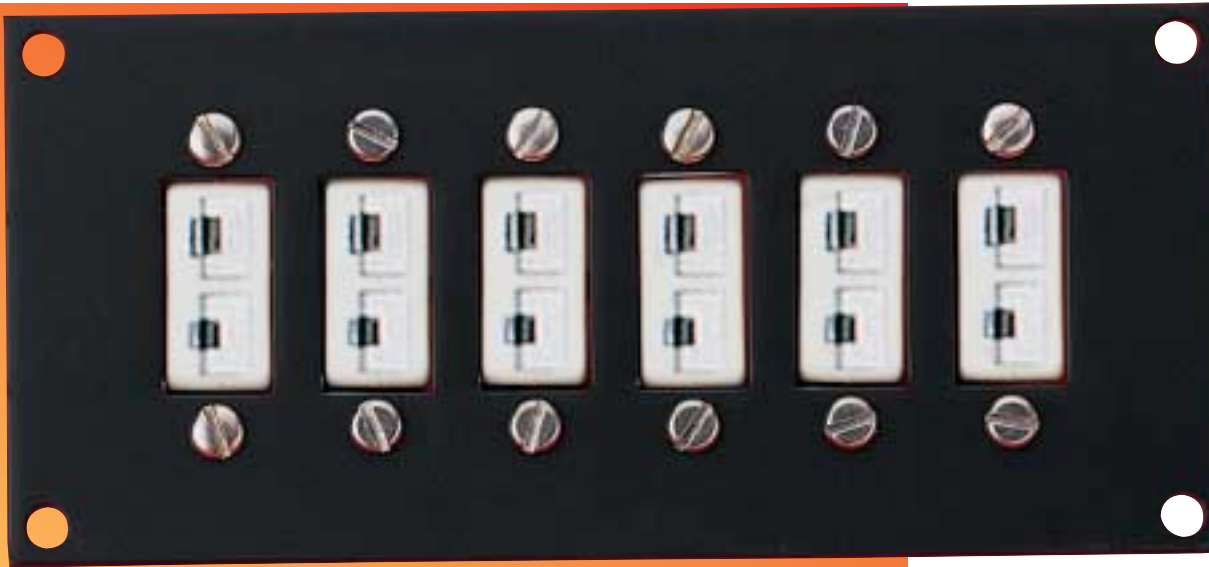

For Service up to 537°C

Circuits Per Rows		1 Row (44.5mm H)	2 Rows (83mm H)	3 Rows (114mm H)	4 Rows (150mm H)
6 (111mm L)	Model No. Price	SHXJP1-06-(*) £62	SHXJP2-12-(*) £100	SHXJP3-18-(*) £142	SHXJP4-24-(*) £183
12 (206mm L)	Model No. Price	SHXJP1-12-(*) £96	SHXJP2-24-(*) £175	SHXJP3-36-(*) £242	SHXJP4-48-(*) £317
18 (302mm L)	Model No. Price	SHXJP1-18-(*) £133	SHXJP2-36-(*) £238	SHXJP3-54-(*) £330	SHXJP4-72-(*) £434

\*Insert Calibration code: J, K, T, N, E, R, S, G, C, D, or U (Uncompensated)

OMEGA® SHXJP jack panels are designed for temperatures up to 537°C, with SHX type subminiature ceramic connectors mounted to a steel plate. They are also available with unglazed connectors, type USHX, for applications where glazed connectors, would contaminate a vacuum system.

**Price and Quantity Discount Information**

The prices listed are for single panels of J, K, T, E, N, R, S, G, C, D or U calibrations.

To order multiple panels, price each panel and connectors separately. Ceramic connectors, type SHX, £5.30 each. Panel mounting bracket, type SHACL, sold separately, £2.50 each. When pricing connectors and mounting brackets, use connector quantity discount schedule below.

See page F-26 for SHX connectors.

See Section G for Wire



Panel Mounting Bracket for SHX Connector.

Type SHACL  
£2.50 ea

4mm dia.  
Screw Holes  
(2 places)

27.75 mm



Panel Opening:  
19.4mm H x 9.9mm W

**Pricing Per Panel**  
(Connectors Sold Separately)

No. of Rows	Price
One	£20.50
Two	24.50
Three	28.50
Four	33.00

**Connector Quantity Discounts**

1-10	.....Net
11-24	.....10%
25-49	.....15%
50-99	.....20%
100 and up	...Consult Sales

