

Universal Jack Panels

Accepts Both **Standard** and **Miniature** Connectors

Most Popular!

IEC
colour
code
shown


To order
ANSI
colour
code see
pg. 49

- ✓ Fully Assembled
- ✓ Snap-in Colour-Coded Jacks
- ✓ Numbered Circuits
- ✓ Easy Installation
- ✓ Convenient
- ✓ Rugged 2.3 mm Aluminium Panel
- ✓ Free Dust Caps Included

4.8 mm

4.8 mm Edge to centre

4.8 mm Dia.

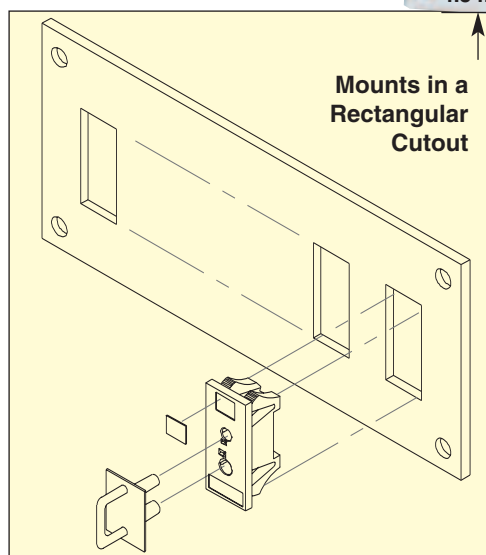

Mounts in a
Rectangular
Cutout

The NEW UJP universal jack panels are the first and only panels that work with both standard and miniature connectors. This innovative design means you don't have to mix standard and mini panels, and it eliminates needless duplication of panel equipment. The jacks are compatible with EVERY standard and miniature connector, no matter what size.

The jacks are moulded of high-impact plastic and have a maximum service temperature of 205°C. The panels are machined from rugged 2.3 mm aluminium with a brushed finish. Clear anodising adds durability and corrosion resistance.

Shown slightly smaller
than actual size

Covered by U.S. and
International Patents and
Pending Applications

In addition to the sizes and styles shown, OMEGA can custom manufacture these universal jack panels to your individual specifications. Simply provide overall dimensions, quantity, number of rows and calibration(s) of jacks desired, and OMEGA will make the panel to meet your needs.

Extra supply of our patented design
Dust Caps: SPJ-CAP-12,
£4.90/pkg of 12

Prices for Single, Off-The-Shelf, Colour-Coded Jack Panels with Standard Connectors

To Order (Specify Model Number) MOST POPULAR MODELS HIGHLIGHTED!					
Circuits Per Row	Dimensions in mm	1 Row H=67mm	2 Rows H=111mm	3 Rows H=168mm	4 Rows H=203mm
6 L=146 mm	Model No. Price†	UJP-1-6-(*)I £42	UJP-2-12-(*)I £67	UJP-3-18-(*)I £94	UJP-4-24-(*)I £122
12 L=260 mm	Model No. Price†	UJP-1-12-(*)I £63	UJP-2-24-(*)I £113	UJP-3-36-(*)I £156	UJP-4-48-(*)I £204
18 L=375 mm	Model No. Price†	UJP-1-18-(*)I £86	UJP-2-36-(*)I £152	UJP-3-54-(*)I £211	UJP-4-72-(*)I £277

* Specify calibration: J, K, T, E, R, S or U. Dust caps included.

† IEC colour models shown.


Price and Quantity Discount Information

The above prices are for J, K, T, E, R, S and U calibrations. To price more than one panel of any type, use the following price schedule:

1 Row.....£16.50 per panel, + jacks
2 Rows.....£20.50 per panel, + jacks
3 Rows.....£24.50 per panel, + jacks
4 Rows.....£28.50 per panel, + jacks

Universal panel jacks, Model No. **UPJ**
Calibrations J, K, T, E, R, S and U:
£4.30 ea. Use connector quantity
discount schedule at right. Blank panel
prices are not discounted.

NOTE: All OMEGA® UJP jack panels are
assembled at no extra cost!

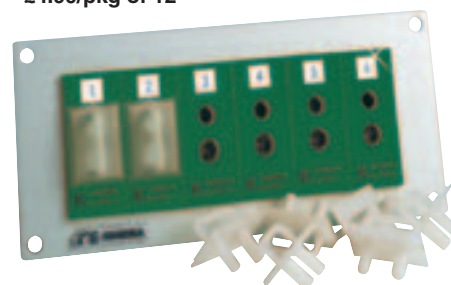

Hole Spacing:

4.8 mm in on both sides,
4.8 mm dia. hole for #8 screw.

Non-Standard Panels

£28 minimum order

Connector Quantity Discounts

1-10 unitsNet
11-24 units10%
25-49 units15%
50-99 units20%
100-999 units25%
1000 and upConsult Sales

Consult Sales Department for
information on custom,
colour-coded anodised panels.

